



KW Series

Compact AC-DC
PCB-Mount Power Supplies

- Small size and lightweight
- PC Board Mountable
- -10 to +70 °C Continuous Operation
- 85 - 265VAC Wide Range Input
- World-wide Agency Approvals UL, CSA, TUV and CE Mark
- Convection Cooled
- Low Noise Conducted EMI Class B

KW Features and Benefits

Features

- Small size
- Wide input range
- No external components needed

Benefits

- Minimises PCB space
- Global use with no manual intervention
- Easy to use

Specifications


ITEMS		MODEL	5V	12V	15V	±12V	±15V
AC Input			85-265VAC 47-440Hz				
DC Input		VDC	110-340VDC				
Efficiency (typical)		%	67-74	70-77	70-77	69-75	69-75
Inrush Current Limiting	(1)	A	5 & 10W: 15/30A, 15W: 20/40A				
Conducted EMI		-	FCC20780 class B, VDE0871 Class B, VCCI-2 (with external cap).				
Output Voltage Accuracy		%	± 5% (fixed)				
Line Regulation		%		0.4%			0.5%
Load Regulation		%		0.8%			5.0%
Ripple and Noise (pk-pk)		mV	120		150		
Hold-up Time (typical)		ms			17ms		
Overvoltage Protection (typical)		%			~110% (zener clamp)		
Overcurrent Protection		-			105%		
Cooling		-			Convection		
Operating Temperature		-	-10°C to 70°C, derate linearly to 25% load from 50°C to 70°C				
Humidity		%RH	30 - 90% (Operating)				
Isolation		VAC	Input to output: 3kVAC; Input to Case: 2kVAC; Output to Case: 500VAC				
Mounting		-	PC board mountable				
Safety Agency Approval		-	UL1950, CSA 22.2 No. 60950-1-03, EN60950-1 & CE Mark (LVD)				
Weight		g	5W: 75, 10W: 100, 15W: 150				
Warranty		-	1 year				

Notes: (1) 100/200VAC @ 25°C

Model Selector			
Model	Voltage (V)	Power (W)	Current (A)
Single Output			
KWS5-5	5V	5	1.00
KWS10-5	5V	10	2.00
KWS15-5	5V	15	3.00
KWS5-12	12V	5	0.45
KWS10-12	12V	10	0.90
KWS15-12	12V	15	1.30
KWS5-15	15V	5	0.35
KWS10-15	15V	10	0.70
KWS15-15	15V	15	1.00
Dual Output			
KWD5-1212	±12V	5	±0.22
KWD10-1212	±12V	10	±0.45
KWD15-1212	±12V	15	±0.65
KWD5-1515	±15V	5	±0.18
KWD10-1515	±15V	10	±0.36
KWD15-1515	±15V	15	±0.52

Pinout Table	
Pin	Function
FG	Case (Frame Ground)
AC(N)	AC Neutral
AC(L)	AC Line
-V	Negative Voltage Out
+V	Positive Voltage Out
COM	Output common

Outline Drawing KW Series

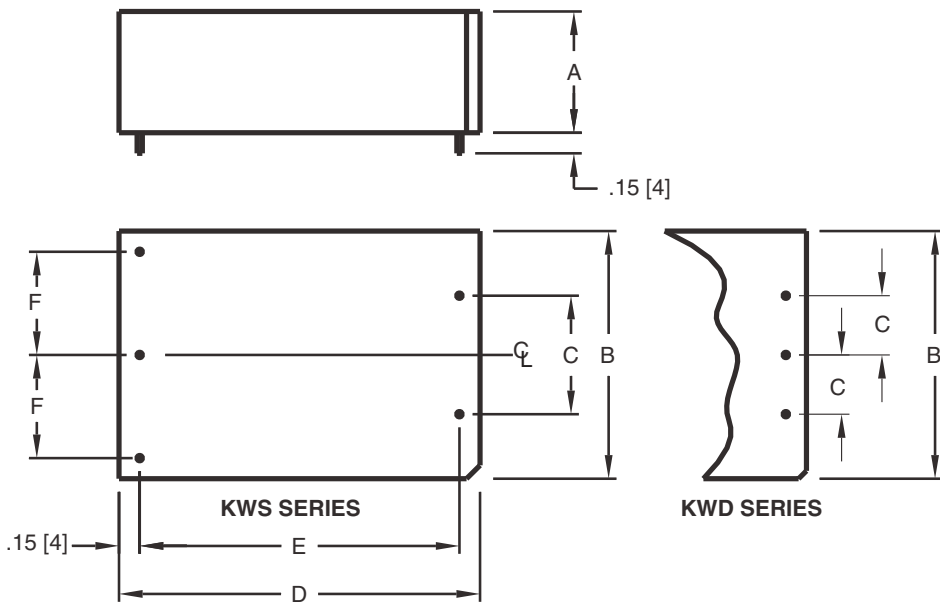

DIMENSIONS:

MODEL	A	B	C	D	E	F
KWS5	.807 (20.5)	1.77 (45.0)	.787 (20.0)	2.16 (55.0)	1.850 (47.0)	.688 (17.5)
KWS10	.807 (20.5)	1.77 (45.0)	.787 (20.0)	2.52 (64.0)	2.125 (54.0)	.688 (17.5)
KWS15	.925 (23.5)	1.889 (48.0)	.905 (23.0)	2.75 (70.0)	2.440 (62.0)	.787 (20.0)
KWD5	.807 (20.5)	1.77 (45.0)	.393 (10.0)	2.16 (55.0)	1.850 (47.0)	.688 (17.5)
KWD10	.807 (20.5)	1.77 (45.0)	.393 (10.0)	2.52 (64.0)	2.125 (54.0)	.688 (17.5)
KWD15	.925 (23.5)	1.889 (48.0)	.453 (11.5)	2.75 (70.0)	2.440 (62.0)	.787 (20.0)

WEIGHT:

MODEL	GRAMS
KWS5	75
KWS10	100
KWS15	150
KWD5	75
KWD10	100
KWD15	150

NOTE:

1. DIMENSIONS ARE IN INCHES
EXCEPT DIMENSIONS () ARE IN MM.

2. PIN: 5x .039 (1.0).

TDK-LAMBDA EMEA

www.emea.tdk-lambda.com



TDK-Lambda France SAS

Route de Grivery
ZAC des Delaches
CS 41077
91978 Courtaboeuf Cedex
France
Tel: +33 1 60 12 71 65
Fax: +33 1 60 12 71 66
france@fr.tdk-lambda.com
www.fr.tdk-lambda.com



Italy Sales Office
Via dei Lavoratori 128/130
20092 Cinisello Balsamo (MI)
Italy
Tel: +39 02 61 29 38 63
Fax: +39 02 61 29 09 00
info.italia@it.tdk-lambda.com
www.it.tdk-lambda.com



TDK-Lambda Germany GmbH

Karl-Bold-Strasse 40
77855 Achern
Germany
Tel: +49 7841 666 0
Fax: +49 7841 5000
info.germany@de.tdk-lambda.com
www.de.tdk-lambda.com



Austria Sales Office
Aredstrasse 22
2544 Leobersdorf
Austria
Tel: +43 2256 655 84
Fax: +43 2256 645 12
info.germany@de.tdk-lambda.com
www.de.tdk-lambda.com



TDK-Lambda UK Ltd.

Kingsley Avenue
Ilfracombe
Devon EX34 8ES
United Kingdom
Tel: +44 (0) 12 71 85 66 66
Fax: +44 (0) 12 71 86 48 94
powersolutions@uk.tdk-lambda.com
www.uk.tdk-lambda.com



Nemic Lambda Ltd.

Kibbutz
Givat Hashlosha 48800
Israel
Tel: +9 723 902 4333
Fax: +9 723 902 4777
info@nemic.co.il
www.nemic.co.il



Russia

Technical Support:
St Petersburg
Tel: +7 (812) 6580463
Sales:
Moscow
Tel: +7 (499) 7557732
info@tdk-lambda.ru
www.tdk-lambda.ru

LOCAL DISTRIBUTION

