


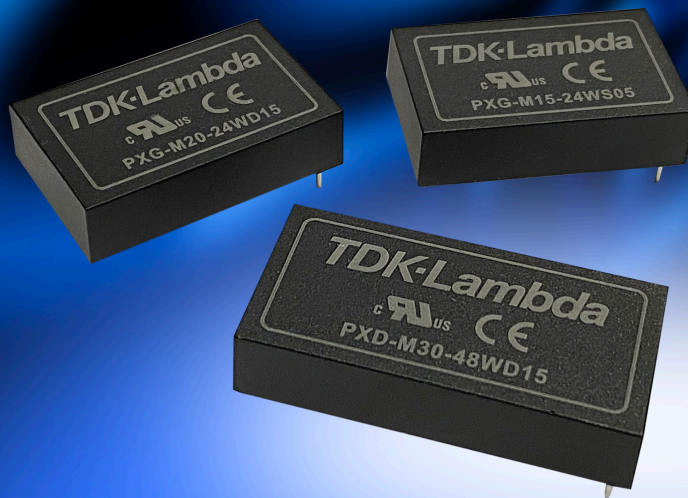

TDK-Lambda

Aspectos Destacados

- Ultra compacto. Convertidor DC/DC de entrada 4:1 (12V, 24V & 48V nominal)
- Aislamiento de 5kVac durante 1 minuto (defibrillator proof)
- 8mm de espacio para tensión de 240Vac, 2MoPP
- 60601-1 3ª edición

Especificaciones Clave

- Tensiones de salida 5, 12, 15, 24V DC and ± 5 , ± 12 , ± 15 Vdc
- Altitud operacional de 5000m
- Encapsulados de 1"x1.6" (PXG) and 1"x2" (PXD)
- Consumo sin carga <75mW

Aplicaciones Típicas

- Equipos médicos
- Cuidados en clínica y domesticos
- Equipos de odontología
- Laboratorios de investigación

Product Highlights

- Ultra compact 4:1 input DC-DC converter (12V, 24V & 48V nominal)
- 5kVac isolation for 1 minute (defibrillator proof)
- 8mm spacing for 240Vac working voltage, 2MoPP
- 60601-1 3rd edition approval

Key Specifications

- 5, 12, 15, 24V DC and ± 5 , ± 12 , ± 15 Vdc outputs
- Altitude operation 5000m
- 1"x1.6" (PXG) and 1"x2" (PXD) package sizes
- No load power <75mW

Typical Applications

- Medical equipment
- Clinical care, Home care
- Dentistry appliances
- Research laboratories