



Special offer for our 20th anniversary

20 YEARS


1998 - 2018

Perfect protection solution for highest performance!

The protection of multiple DC loads in case of one load failure (selectivity) is elegantly solved by the digital overcurrent protector **NEF210** (2 independent channels, each settable 2...10A).

Advantages:

- Compact, circuit breaker shape
- Programmable tripping thresholds and curves, suitable for any load 10...30Vdc
- Extensive data logging
- Can be used as static switch
- Remote monitoring and setting by **POWERMASTER™** application (Windows, Android)

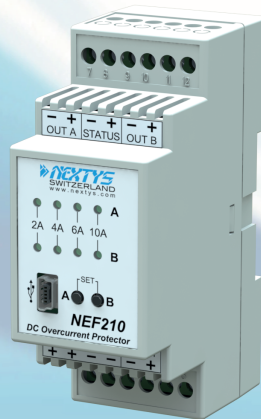

Bundle 1

NEF210

+

NDD120-XXYY




Bundle 2

NEF210

+

NPSM501-24

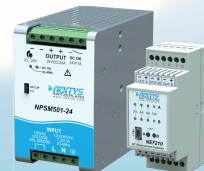

Bundle 1

NDD120-XXYY* + NEF210
(Order ID: **PROM1-XXYY***)



NDD120-1224/2424/4824/2412
120W, compact, isolated DC/DC Converter
(*) **XX** = input voltage and **YY** = output voltage

NEF210
Dual channel
Digital overcurrent protector 10A/channel



90.00€

(Incoterms: EX-WORKS, excluding VAT)



Validity until exhaust of stock.
For product information and orders:
sales@nextys.com
+41 (0)91 840 14 48

NEXTYS
www.nextys.com

Bundle 2

NPSM501-24 + NEF210
(Order ID: **PROM2**)



NPSM501-24
480W, compact power supply
1 phase input - output 24Vdc/20A

NEF210
Dual channel
Digital overcurrent protector 10A/channel



130.00€

(Incoterms: EX-WORKS, excluding VAT)